



COMPONENTS	IMPEDANCE
SMA MALE	50 OHM
SMA MALE	50 OHM
RG400/U	50 OHM

Standard Lengths	
-12	12"
-24	24"
-36	36"
-48	48"
-60	60"
-XXX	Custom Length in inches

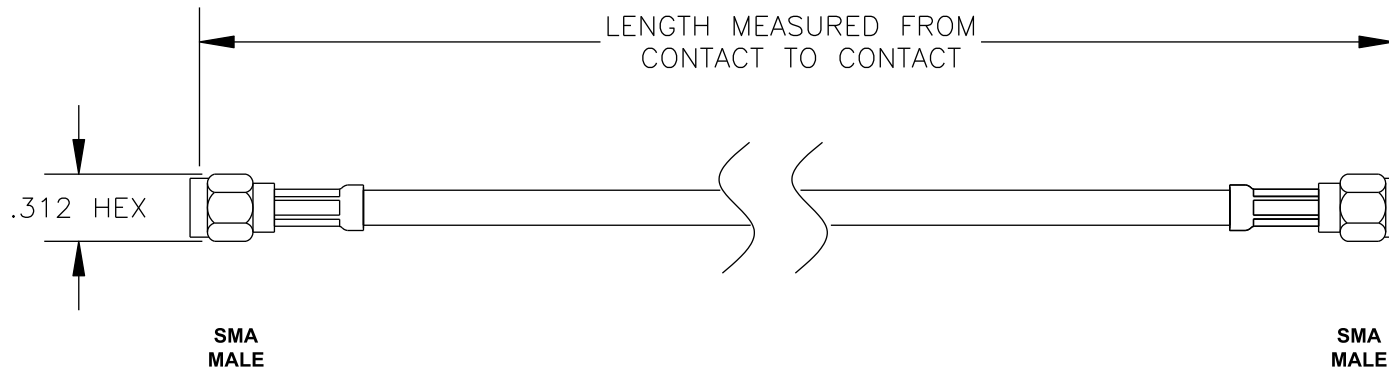

 <p><b>PASTERNAK ENTERPRISES, INC.</b>  P.O BOX 16759, IRVINE, CA 92623  PHONE (949) 261-1920 FAX (949) 261-7451  WEB ADDRESS: <a href="http://www.pasternack.com">www.pasternack.com</a>  E-MAIL ADDRESS: <a href="mailto:sales@pasternack.com">sales@pasternack.com</a>  <b>COAXIAL &amp; FIBER OPTICS</b></p>						
		<b>DWG TITLE</b> <b>PE3500-XX</b>				
<b>DES.</b> CABLE ASSEMBLY, RG400/U, SMA MALE TO SMA MALE		<b>REV. A</b>	<b>FSCM NO. 53919</b>	<b>CAD FILE</b> 021208	<b>SCALE</b> N/A	<b>SIZE</b> A 127

- NOTES:**
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
  2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
  3. DIMENSIONS ARE IN INCHES.
  4. LENGTH TOLERANCE IS  $\pm 1.5\%$  OR  $\pm 3/8"$ , WHICHEVER IS GREATER.