


COMPONENTS	IMPEDANCE
N MALE RIGHT ANGLE	50 OHM
N MALE RIGHT ANGLE	50 OHM
RG142B/U	50 OHM

Standard Lengths	
-12	12"
-24	24"
-36	36"
-48	48"
-60	60"
-XXX	Custom Length in inches

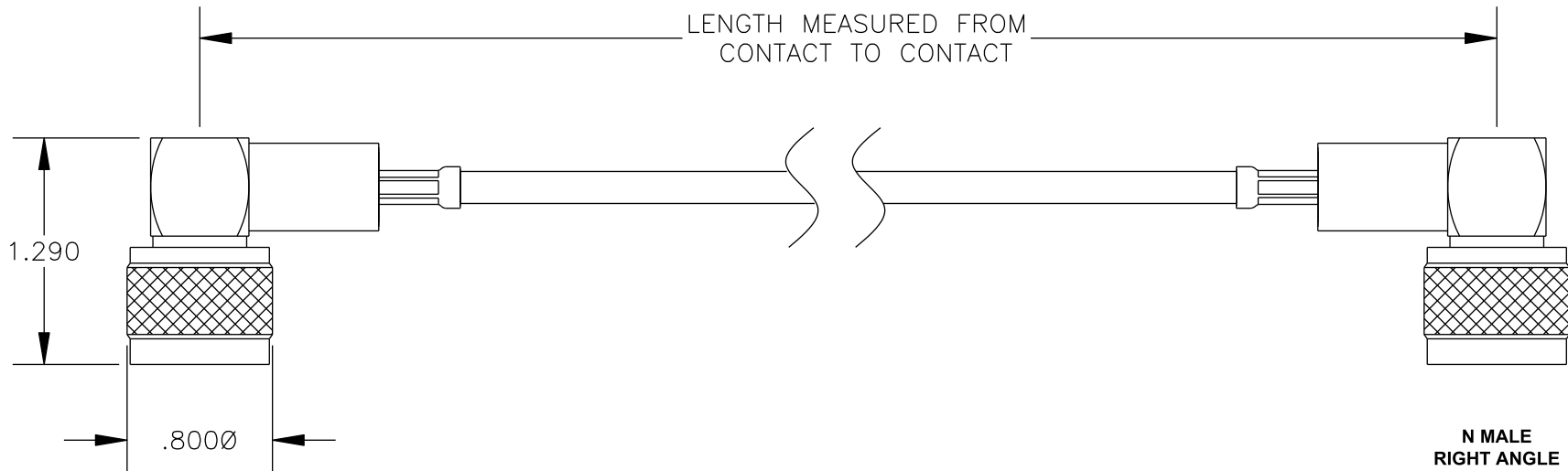

N MALE
RIGHT ANGLE

N MALE
RIGHT ANGLE



PASTERNAK ENTERPRISES, INC.
 P.O BOX 16759, IRVINE, CA 92623
 PHONE (949) 261-1920 FAX (949) 261-7451
 WEB ADDRESS: www.pasternack.com
 E-MAIL ADDRESS: sales@pasternack.com
COAXIAL & FIBER OPTICS



RoHS
Compliance
Certified

DWG TITLE	DES.
PE3693LF-XX	CABLE ASSEMBLY, RG142B/U, N MALE RIGHT ANGLE TO N MALE RIGHT ANGLE (LEAD FREE)

REV. A	FSCM NO. 53919	CAD FILE 021108	SCALE N/A	SIZE A 127
--------	----------------	-----------------	-----------	------------

- NOTES:**
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES.
 4. LENGTH TOLERANCE IS $\pm 1.5\%$ OR $\pm 3/8"$, WHICHEVER IS GREATER.