



SMA Male Field Replaceable Connector With EMI Gasket
4 Hole Flange 0.015 inch Pin, .500 inch Flange Size

TECHNICAL DATA SHEET

PE44019

Configuration

Connector	SMA Male
Connector Interface Type	0.015 inch Pin
Cable Attachment Method (Shield/Contact)	Field Replaceable
Body Style	Straight
Mount Method	4 Hole Flange
Option	EMI Gasket

Electrical Specifications

Impedance, Ohms	50
-----------------	----

Mechanical Specifications

Size

Length, in [mm]	0.5 [12.7]
Width/Dia., in [mm]	0.5 [12.70]
Height, in [mm]	0.5 [12.7]
Weight, lbs [g]	0.013 [5.9]

Connector

Type	SMA Male
Contact Material and Plating	Gold
Coupling Nut Material and Plating	Brass, Nickel
Hex Size, in.	5/16
Torque, in-lbs [Nm]	5 [0.57]
Body Material and Plating	Passivated Stainless Steel
Dielectric Type	PTFE

Compliance Certifications (visit www.Pasternack.com for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [SMA Male Field Replaceable Connector With EMI Gasket 4 Hole Flange 0.015 inch Pin, .500 inch Flange Size PE44019](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.





SMA Male Field Replaceable Connector With EMI Gasket
4 Hole Flange 0.015 inch Pin, .500 inch Flange Size

TECHNICAL DATA SHEET

PE44019

Plotted and Other Data

Notes:

Values at 25 °C, sea level

SMA Male Field Replaceable Connector With EMI Gasket 4 Hole Flange 0.015 inch Pin, .500 inch Flange Size from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [SMA Male Field Replaceable Connector With EMI Gasket 4 Hole Flange 0.015 inch Pin, .500 inch Flange Size PE44019](#)

URL: <http://www.pasternack.com/sma-male-standard-0.015-pin-connector-pe44019-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

PE44019 CAD Drawing

SMA Male Field Replaceable Connector With EMI Gasket
4 Hole Flange 0.015 inch Pin, .500 inch Flange Size

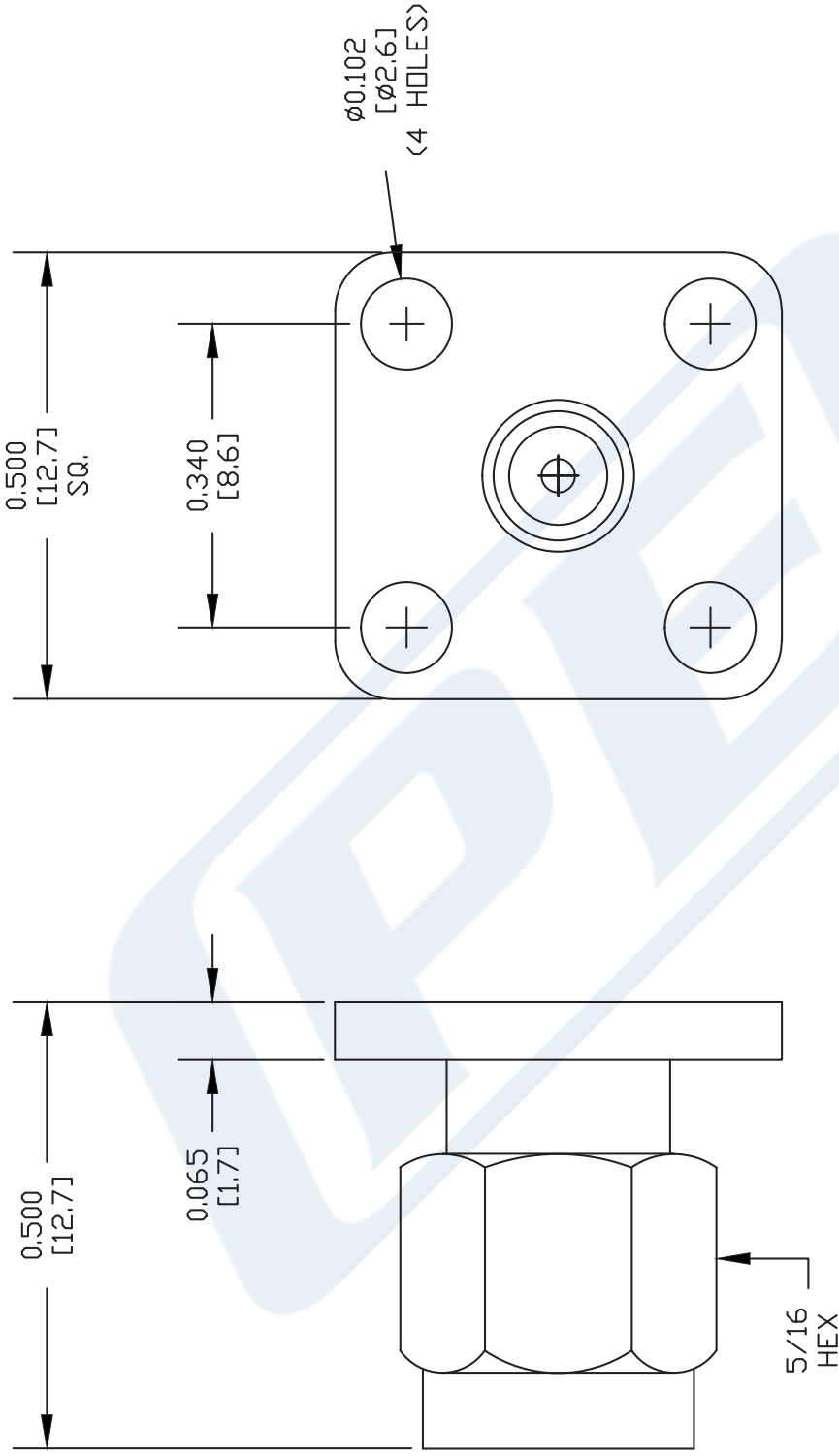

NOTES:
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES [mm].
 4. FITS MIL-C-17 AND EQUIVALENT CABLES.

DWG TITLE
PE44019

FSCM NO. 53919

PE PASTERNAK®
 Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623
 Phone: (949) 261-1920 | Fax: (949) 261-7451
 Website: www.pasternack.com | E-Mail: sales@pasternack.com

CAD FILE 061902 SCALE N/A SIZE A 127