



SMB Jack Connector Solder Attachment 0.042 inch
End Launch PCB, .030 inch Diameter

TECHNICAL DATA SHEET

PE44132

SMB Jack Connector Solder Attachment 0.042 inch End Launch PCB, .030 inch Diameter

Configuration

Connector	SMB Jack
Connector Specification	MIL-C-39012
Connector Interface Type	0.042 inch End Launch
Cable Attachment Method (Shield/Contact)	Solder
Body Style	Straight

Electrical Specifications

Frequency Range, GHz	DC to 4
Impedance, Ohms	50
Maximum Operating Voltage, Volts	335
Dielectric Withstanding Voltage, Vrms	1,000

Mechanical Specifications

Temperature

Operating Range, deg C	-65 to +165
------------------------	-------------

Size

Length, in [mm]	0.562 [14.27]
Width/Dia., in [mm]	0.375 [9.53]
Height, in [mm]	0.312 [7.92]
Weight, lbs [g]	0.004 [1.81]

Connector

Type	SMB Jack
Mating Cycles	500
Contact Material and Plating	Brass, Gold
Contact Plating Specification	30µ in. minimum
Body Material and Plating	Brass, Gold
Body Plating Specification	10µ in. minimum
Dielectric Type	Teflon

Compliance Certifications (visit www.Pasternack.com for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [SMB Jack Connector Solder Attachment 0.042 inch End Launch PCB, .030 inch Diameter PE44132](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.



SMB Jack Connector Solder Attachment 0.042 inch
End Launch PCB, .030 inch Diameter

TECHNICAL DATA SHEET

PE44132

Plotted and Other Data

Notes:

Values at 25 °C, sea level

SMB Jack Connector Solder Attachment 0.042 inch End Launch PCB, .030 inch Diameter from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [SMB Jack Connector Solder Attachment 0.042 inch End Launch PCB, .030 inch Diameter PE44132](http://www.pasternack.com/smb-jack-standard-0.042-end-launch-connector-pe44132-p.aspx)

URL: <http://www.pasternack.com/smb-jack-standard-0.042-end-launch-connector-pe44132-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

PE44132 CAD Drawing

SMB Jack Connector Solder Attachment 0.042 inch End Launch PCB, .030 inch Diameter

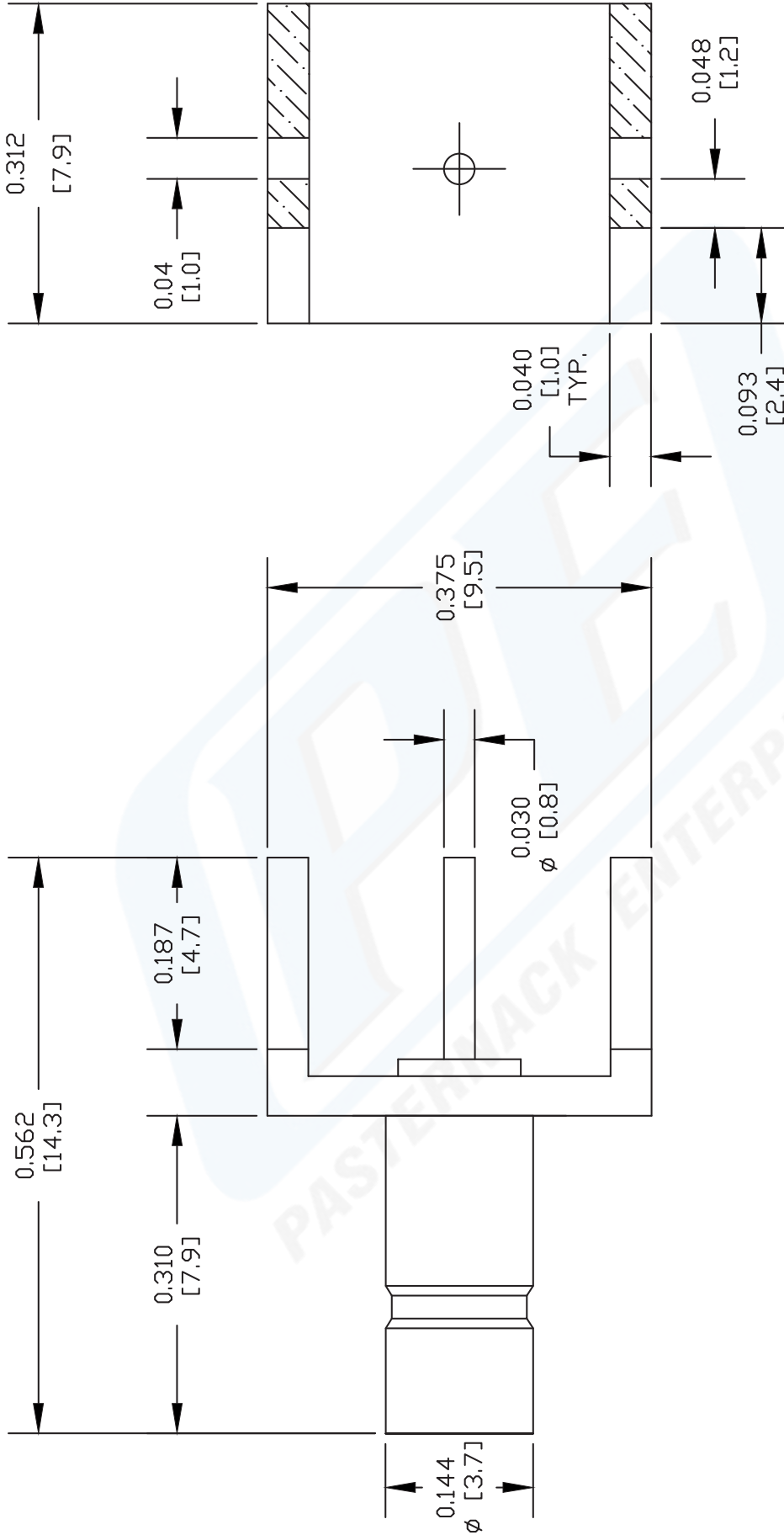

NOTES:
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES [mm].
 4. FITS MIL-C-17 AND EQUIVALENT CABLES.

DWG TITLE
PE44132

FSCM NO. 53919

127

PE PASTERNAK®
 Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623
 Phone: (949) 261-1920 | Fax: (949) 261-7451
 Website: www.pasternack.com | E-Mail: sales@pasternack.com