



2.92mm Male Connector Field Replaceable Attachment
4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing

TECHNICAL DATA SHEET

PE44233

2.92mm Male Connector Field Replaceable Attachment 4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing

Configuration

Connector	2.92mm Male
Connector Interface Type	0.012 inch Pin
Cable Attachment Method (Shield/Contact)	Field Replaceable
Body Style	Straight
Mount Method	4 Hole Flange

Electrical Specifications

Impedance, Ohms	50
-----------------	----

Mechanical Specifications

Size

Length, in [mm]	0.506 [12.85]
Width/Dia., in [mm]	0.5 [12.70]
Height, in [mm]	0.5 [12.7]
Weight, lbs [g]	0.013 [5.9]

Connector

Type	2.92mm Male
Contact Material and Plating	Gold
Coupling Nut Material and Plating	Brass, Nickel
Hex Size, in.	5/16
Torque, in-lbs [Nm]	5 [0.57]
Body Material and Plating	Passivated Stainless Steel
Dielectric Type	PPO

Compliance Certifications (visit www.Pasternack.com for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [2.92mm Male Connector Field Replaceable Attachment 4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing PE44233](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.



2.92mm Male Connector Field Replaceable Attachment
4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing

TECHNICAL DATA SHEET

PE44233

Plotted and Other Data

Notes:

Values at 25 °C, sea level

2.92mm Male Connector Field Replaceable Attachment 4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [2.92mm Male Connector Field Replaceable Attachment 4 Hole Flange 0.012 inch Pin, .340 inch Hole Spacing PE44233](http://www.pasternack.com/2.92mm-male-standard-0.012-pin-connector-pe44233-p.aspx)

URL: <http://www.pasternack.com/2.92mm-male-standard-0.012-pin-connector-pe44233-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

PE44233 CAD Drawing

2.92mm Male Connector Field Replaceable Attachment 4 Hole
Flange 0.012 inch Pin, .340 inch Hole Spacing

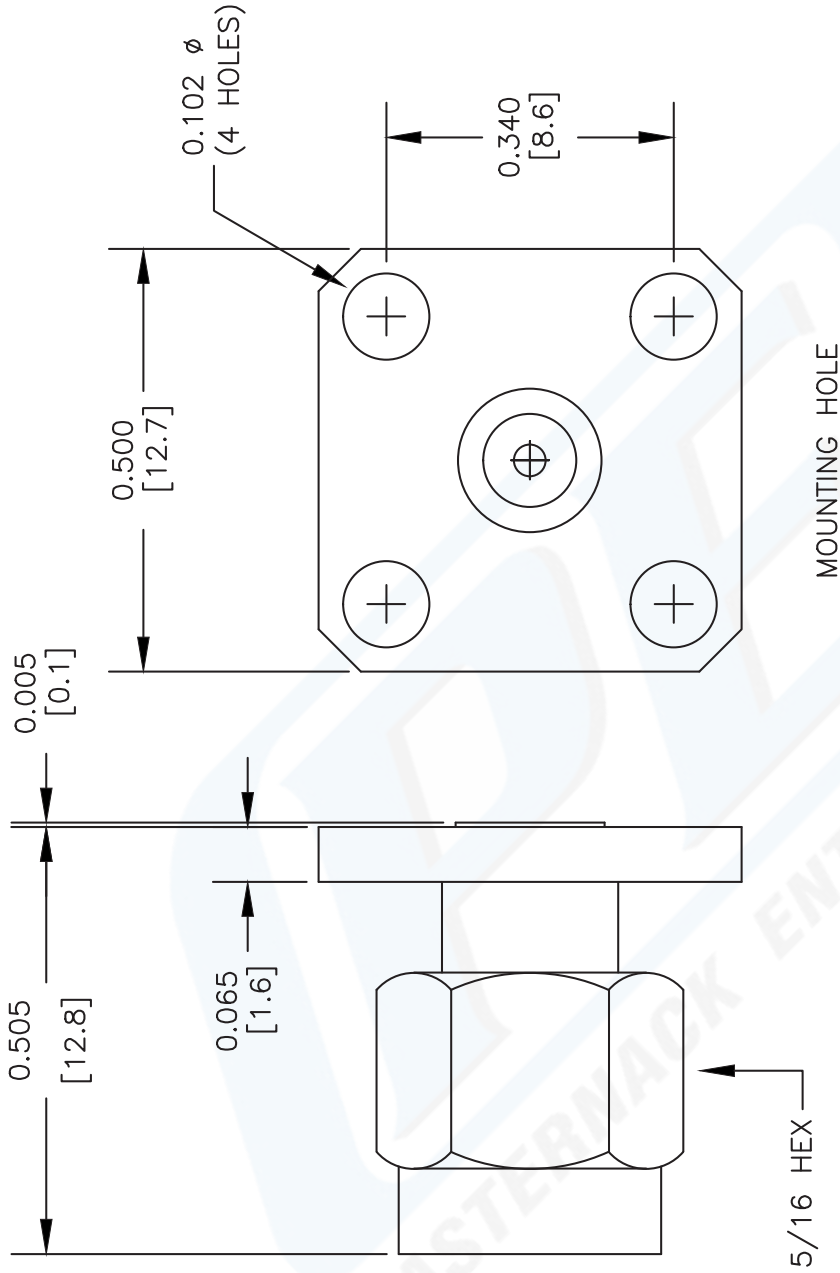

DWG TITLE

PE44233

NOTES:
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
3. DIMENSIONS ARE IN INCHES [mm].
4. FITS MIL-C-17 AND EQUIVALENT CABLES.

FSCM NO. 53919

CAD FILE 070202

SCALE N/A

SIZE A

127



Pasternack Enterprises, Inc.
P.O. Box 16759 | Irvine | CA | 92623
Phone: (949) 261-1920 | Fax: (949) 261-7451
Website: www.pasternack.com | E-Mail: sales@pasternack.com