



RP MCX Jack Right Angle Bulkhead Connector Solder Attachment Thru Hole PCB, .177 inch D Hole

TECHNICAL DATA SHEET

PE44376

**RP MCX Jack Right Angle Bulkhead Connector Solder Attachment Thru Hole PCB, .177 inch D Hole**

**Configuration**

Connector	MCX Jack Reverse Polarity
Connector Specification	MIL-C-39012
Connector Interface Type	Thru Hole
Cable Attachment Method (Shield/Contact)	Solder
Body Style	Right Angle
Mount Method	Bulkhead

**Electrical Specifications**

Frequency Range, GHz	DC to 6
Impedance, Ohms	50
Maximum Operating Voltage, Volts	335
Dielectric Withstanding Voltage, Vrms	1,000

**Mechanical Specifications**

**Temperature**

Operating Range, deg C	-65 to +165
------------------------	-------------

**Size**

Length, in [mm]	0.535 [13.59]
Width/Dia., in [mm]	0.25 [6.35]
Height, in [mm]	0.368 [9.35]
Weight, lbs [g]	0.006 [2.72]

**Connector**

Type	MCX Jack Reverse Polarity
Mating Cycles	500
Contact Material and Plating	Brass, Gold
Contact Plating Specification	30µ in minimum
Body Material and Plating	Brass, Gold
Body Plating Specification	10µ in minimum
Dielectric Type	Teflon

**Compliance Certifications** (visit [www.Pasternack.com](http://www.Pasternack.com) for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [RP MCX Jack Right Angle Bulkhead Connector Solder Attachment Thru Hole PCB, .177 inch D Hole PE44376](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.



RP MCX Jack Right Angle Bulkhead Connector Solder  
Attachment Thru Hole PCB, .177 inch D Hole

TECHNICAL DATA SHEET

PE44376

**Plotted and Other Data**

Notes:

Values at 25 °C, sea level

RP MCX Jack Right Angle Bulkhead Connector Solder Attachment Thru Hole PCB, .177 inch D Hole from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [RP MCX Jack Right Angle Bulkhead Connector Solder Attachment Thru Hole PCB, .177 inch D Hole PE44376](http://www.pasternack.com/mcx-jack-reverse-polarity-thru-hole-pcb-connector-pe44376-p.aspx)

URL: <http://www.pasternack.com/mcx-jack-reverse-polarity-thru-hole-pcb-connector-pe44376-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

# PE44376 CAD Drawing

RP MCX Jack Right Angle Bulkhead Connector Solder  
Attachment Thru Hole PCB, .177 inch D Hole

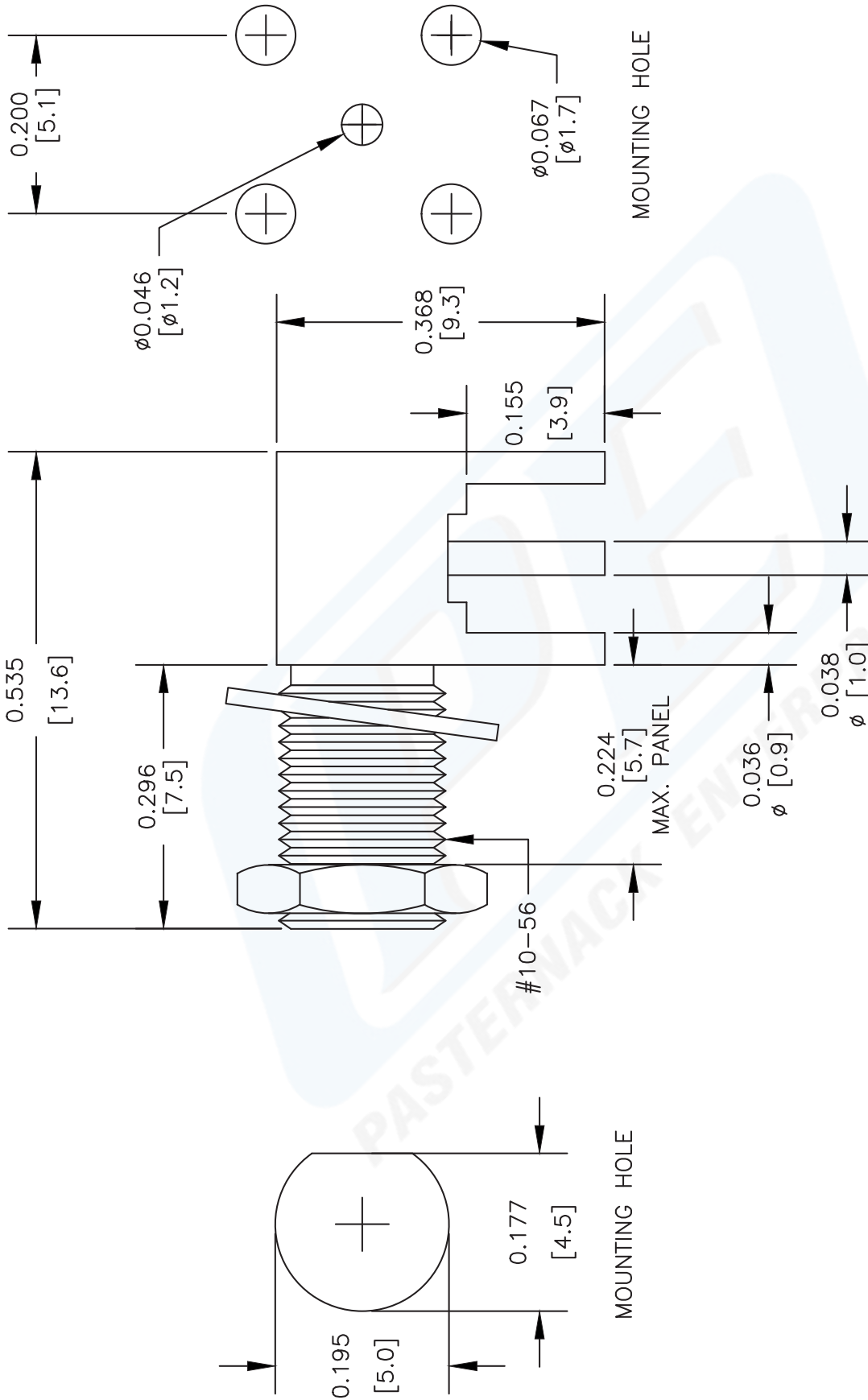

DWG TITLE

**PE44376**

- NOTES:
1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
  2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
  3. DIMENSIONS ARE IN INCHES [mm].
  4. FITS MIL-C-17 AND EQUIVALENT CABLES.

FSCM NO. 53919

CAD FILE 072403

SCALE N/A

SIZE A

127



**PASTERNAK®**  
Pasternack Enterprises, Inc.  
P.O. Box 16759 | Irvine | CA | 92623  
Phone: (949) 261-1920 | Fax: (949) 261-7451  
Website: www.pasternack.com | E-Mail: sales@pasternack.com