



75 Ohm BNC Female Connector Solder Attachment
4 Hole Flange Turret Terminal, .531 inch Hole Spacing

TECHNICAL DATA SHEET

PE4618

75 Ohm BNC Female Connector Solder Attachment 4 Hole Flange Turret Terminal, .531 inch Hole Spacing

Configuration

Connector	BNC Female
Connector Interface Type	Turret
Cable Attachment Method (Shield/Contact)	Solder
Body Style	Straight
Mount Method	4 Hole Flange

Electrical Specifications

Impedance, Ohms	75
-----------------	----

Mechanical Specifications

Size

Length, in [mm]	1.07 [27.18]
Width/Dia., in [mm]	0.75 [19.05]
Height, in [mm]	0.75 [19.05]
Weight, lbs [g]	0.013 [5.9]

Connector

Type	BNC Female
Contact Material and Plating	Silver
Body Material and Plating	Brass, Nickel
Dielectric Type	Teflon

Compliance Certifications (visit www.Pasternack.com for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [75 Ohm BNC Female Connector Solder Attachment 4 Hole Flange Turret Terminal, .531 inch Hole Spacing PE4618](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.



75 Ohm BNC Female Connector Solder Attachment
4 Hole Flange Turret Terminal, .531 inch Hole Spacing

TECHNICAL DATA SHEET

PE4618

Plotted and Other Data

Notes:

Values at 25 °C, sea level

75 Ohm BNC Female Connector Solder Attachment 4 Hole Flange Turret Terminal, .531 inch Hole Spacing from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.



Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [75 Ohm BNC Female Connector Solder Attachment 4 Hole Flange Turret Terminal, .531 inch Hole Spacing PE4618](http://www.pasternack.com/bnc-female-standard-turret-terminal-connector-pe4618-p.aspx)

URL: <http://www.pasternack.com/bnc-female-standard-turret-terminal-connector-pe4618-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

PE4618 CAD Drawing

75 Ohm BNC Female Connector Solder Attachment 4 Hole
Flange Turret Terminal, .531 inch Hole Spacing

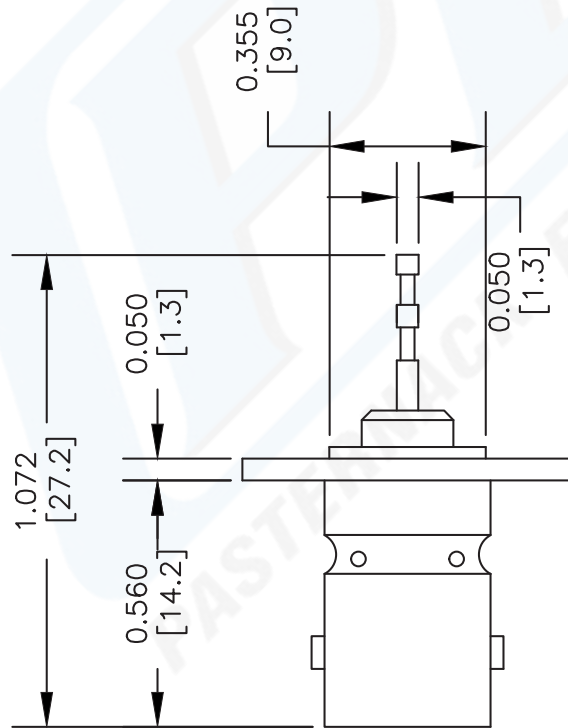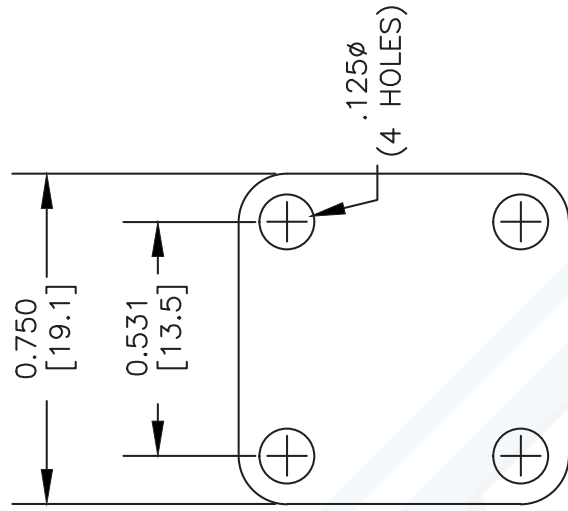

NOTES:
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.
 3. DIMENSIONS ARE IN INCHES [mm].

DWG TITLE
PE4618

FSCM NO. 53919

XXXX

SIZE A

SCALE N/A

CAD FILE 052902

PE PASTERNAK®
 Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623
 Phone: (949) 261-1920 | Fax: (949) 261-7451
 Website: www.pasternack.com | E-Mail: sales@pasternack.com