



50 Ohm 0.5 Watts Precision 2.92mm Female  
RF Load With Chain Up To 40 GHz

TECHNICAL DATA SHEET

PE6088

**50 Ohm 0.5 Watts Precision Passivated Stainless Steel 2.92mm Female RF Load With Chain Up To 40 GHz**

Pasternack Enterprises line of 2.92mm Terminations are available in 0.5 Watt, 1 Watt and 2 Watt versions and operate from DC to 40 GHz. Our 2.92mm Terminations are manufactured for durability with Passivated Stainless Steel bodies and Gold Plated BeCu (Beryllium Copper) contacts and are with a Chain or No Chain. Pasternack's Male and Female 2.92mm Terminations will mate with 2.92mm, 3.5mm and SMA connectors.

- DC to 40 GHz
- 0.5W, 1W and 2W versions
- Passivated Stainless Steel bodies
- Gold plated BeCu contacts
- Chain and No Chain options

**Configuration**

RF Load Design	Precision
Connector	2.92mm Female
Connection Method	Standard
Body Style	Straight

**Electrical Specifications**

Frequency Range, GHz	DC to 40
Impedance, Ohms	50
Maximum VSWR	1.2:1
Maximum Input Power, Watts	0.5

**Mechanical Specifications**

**Size**

Length, in [mm]	0.52 [13.21]
Width/Dia., in [mm]	0.25 [6.35]

**Connector**

Type	2.92mm Female
------	---------------

**Compliance Certifications** (visit [www.Pasternack.com](http://www.Pasternack.com) for current document)

RoHS Compliant	Yes
----------------	-----

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [50 Ohm 0.5 Watts Precision Passivated Stainless Steel 2.92mm Female RF Load With Chain Up To 40 GHz PE6088](#)

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.



50 Ohm 0.5 Watts Precision 2.92mm Female  
RF Load With Chain Up To 40 GHz

TECHNICAL DATA SHEET

PE6088

**Plotted and Other Data**

Notes:

Values at 25 °C, sea level

50 Ohm 0.5 Watts Precision 2.92mm Female RF Load With Chain Up To 40 GHz from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and fiber optic products maintain a 99% availability and are part of the broadest selection in the industry.


Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [50 Ohm 0.5 Watts Precision Passivated Stainless Steel 2.92mm Female RF Load With Chain Up To 40 GHz PE6088](http://www.pasternack.com/292mm-female-precision-termination-pe6088-p.aspx)

URL: <http://www.pasternack.com/292mm-female-precision-termination-pe6088-p.aspx>

The information contained in this document is accurate to the best of our knowledge and representative of the part described herein. It may be necessary to make modifications to the part and/or the documentation of the part, in order to implement improvements. Pasternack reserves the right to make such changes as required. Unless otherwise stated, all specifications are nominal.

# PE6088 CAD Drawing

50 Ohm 0.5 Watts Precision 2.92mm Female RF Load With Chain Up To 40 GHz

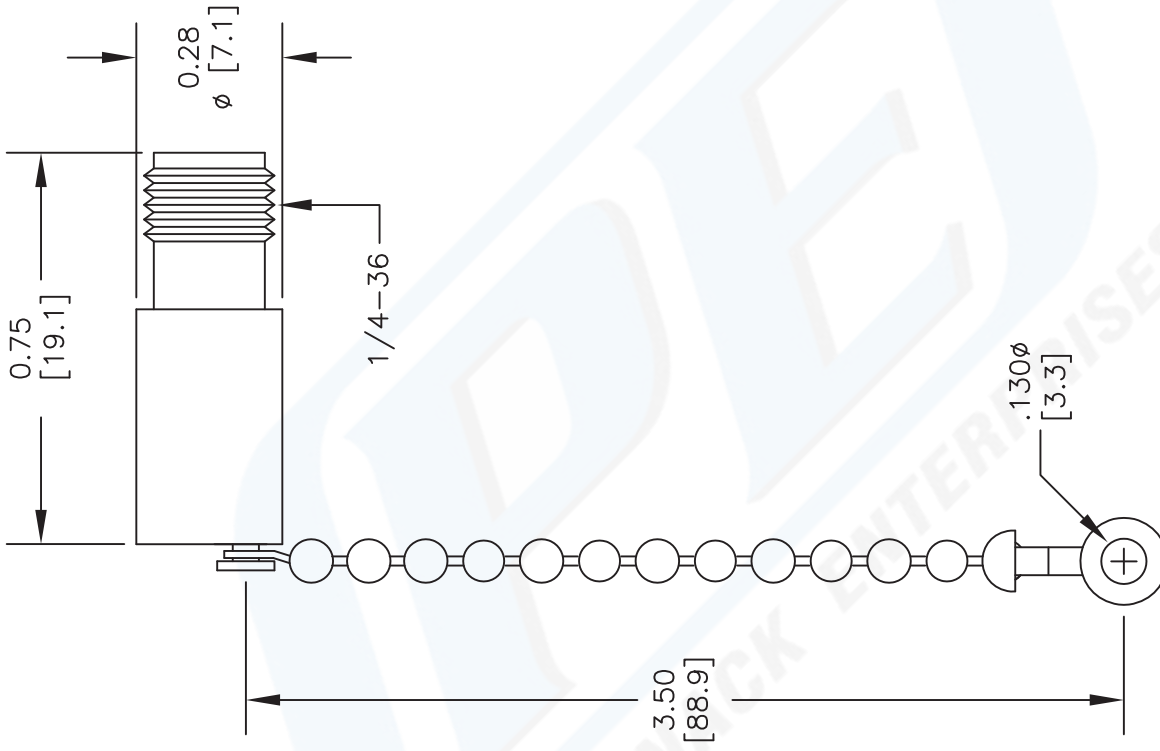

NOTES:  
 1. UNLESS OTHERWISE SPECIFIED ALL DIMENSIONS ARE NOMINAL.  
 2. ALL SPECIFICATIONS ARE SUBJECT TO CHANGE WITHOUT NOTICE AT ANY TIME.  
 3. DIMENSIONS ARE IN INCHES [mm].

DWG TITLE  
**PE6088**

FSCM NO. 53919

CAD FILE 060807 SCALE N/A SIZE A 127

**PE PASTERNAK**  
 Pasternack Enterprises, Inc.  
 P.O. Box 16759 | Irvine | CA | 92623  
 Phone: (949) 261-1920 | Fax: (949) 261-7451  
 Website: www.pasternack.com | E-Mail: sales@pasternack.com