



Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm

Electrical Specifications

Description	Minimum	Typical	Maximum	Units
Frequency Range	26.5		40	GHz
Impedance		50		Ohms
Phase Shift	0		360	Degrees
Input VSWR			2:1	
Group Delay			670	ps
Input Power, CW			20	Watts

Mechanical Specifications

Size

Length	6.91 in [175.51 mm]
Width/Diameter	2 in [50.8 mm]
Height	1 in [25.4 mm]
Weight	1.12 lbs [508.02 g]
Finish	BL
Body Material and Plating	Aluminum

Configuration

Input Connector	2.92mm Female
Output Connector	2.92mm Female

Environmental Specifications

Compliance Certifications (see [product page](#) for current document)

Plotted and Other Data

Notes:

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm PE8254](#)



Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm

Phase Shifters and Trimmers Technical Data Sheet

PE8254


Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm from Pasternack Enterprises has same day shipment for domestic and International orders. Our RF, microwave and millimeter wave products maintain a 99% availability and are part of the broadest selection in the industry.

Click the following link (or enter part number in "SEARCH" on website) to obtain additional part information including price, inventory and certifications: [Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm PE8254](https://www.pasternack.com/adjustable-phase-shifter-40-ghz-2.92mm-30-deg-per-ghz-pe8254-p.aspx)

URL: <https://www.pasternack.com/adjustable-phase-shifter-40-ghz-2.92mm-30-deg-per-ghz-pe8254-p.aspx>

PE8254 CAD Drawing

Adjustable Phase Shifter, 26.5 GHz to 40 GHz, With an Adjustable Phase Range of 0 to 360 Degrees and 2.92mm

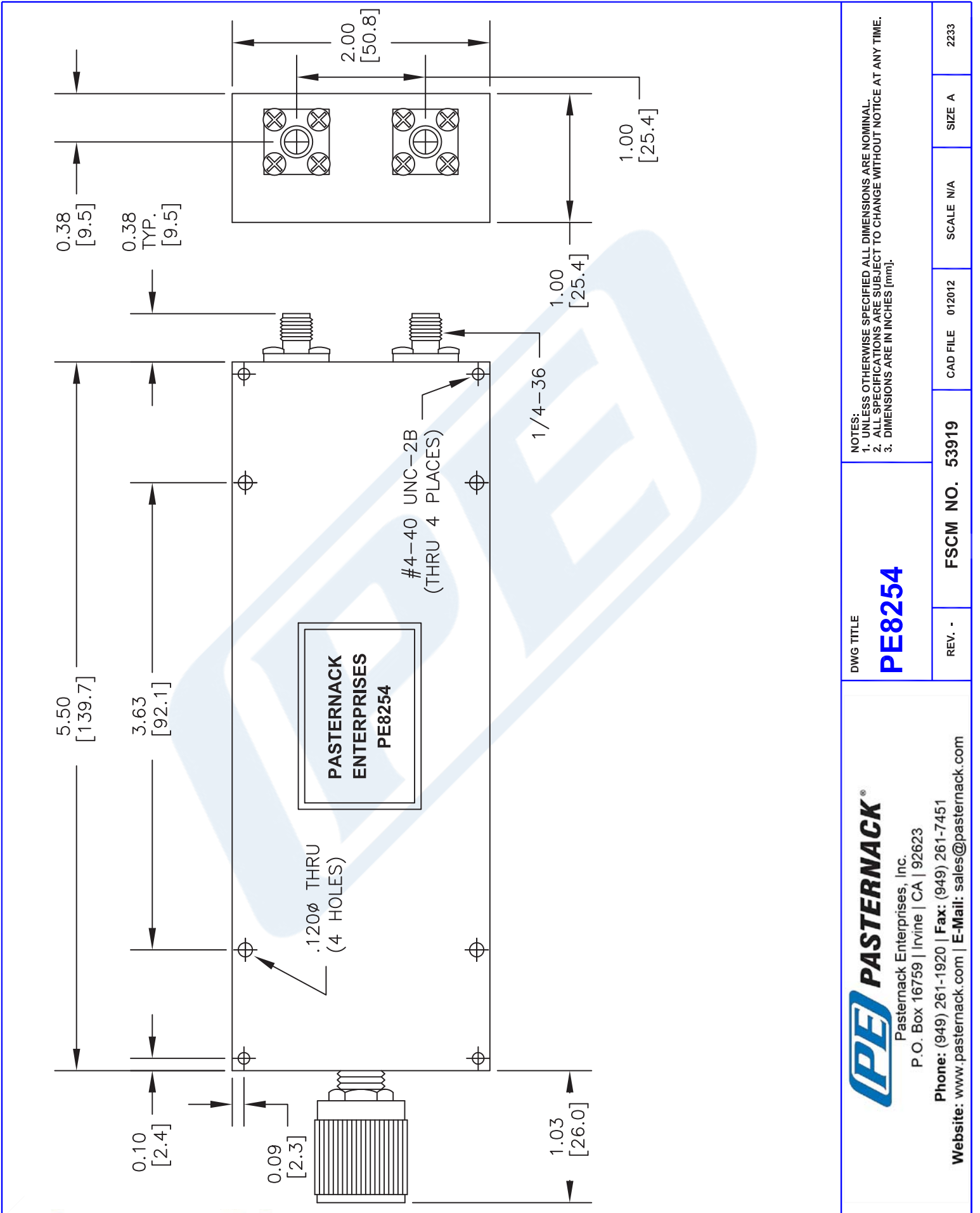

DWG TITLE

PE8254

REV. -

FSCM NO. 53919

CAD FILE 012012

SCALE N/A

SIZE A

2233



Pasternack Enterprises, Inc.
 P.O. Box 16759 | Irvine | CA | 92623
 Phone: (949) 261-1920 | Fax: (949) 261-7451
 Website: www.pasternack.com | E-Mail: sales@pasternack.com