


REV. STATUS SHEETS	REV. LTR.	REVISIONS					
	1	DESCRIPTION	DATE	BY			
		Released	6/20/96	JCL			

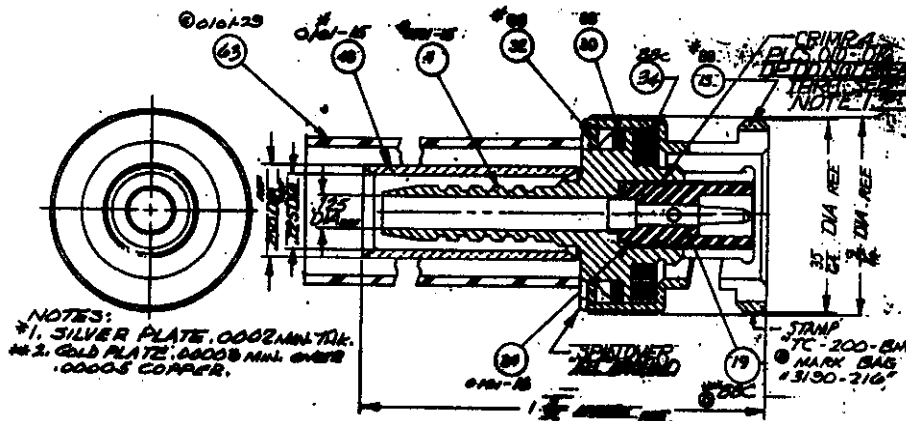

**Materials & Finishes**

Center Contact: Gold(30u" over 50u" Copper) Plated Brass; Soldered  
 outer Contact: Silver(200u") Plated Brass; Crimped  
 Other Metal Parts: Silver(200u") Plated Brass  
 Dielectric: Teflon  
 Gasket: Silicone Rubber

**Electrical Properties**

Impedance: 50 Ohms  
 Working Voltage: 500 volts (RMS max)  
 VSWR: 1.25:1 (max) up to 2 GHz  
 Insertion Loss: <0.1 dB up to 2 GHz

Unless otherwise specified dimensions in inches. Tolerances are applicable when specified.	Approvals			TIMES MICROWAVE SYSTEMS Wallingford, CT 06492		
	Drawn	JCL	6/20/96	TC-200-BM Type BNC Male Connector for LMR-200		
	Check					
	PrjMg					
	PrdMg			Size A	Code Ident 68999	Dwg.No. 3190-225
	QAMgr			Scale: NA	Sheet: 1 of 1	